


DODGE® ECCENTRIC COLLAR MOUNTED BALL BEARINGS

Dodge eccentric collar mounted ball bearings, with a rugged design and precision construction for maximum life and equipment uptime, have been manufactured in Rogersville, TN since 1971. We know that manufacturing locally allows us to consistently produce high quality, reliable products, and respond to customer needs quickly.

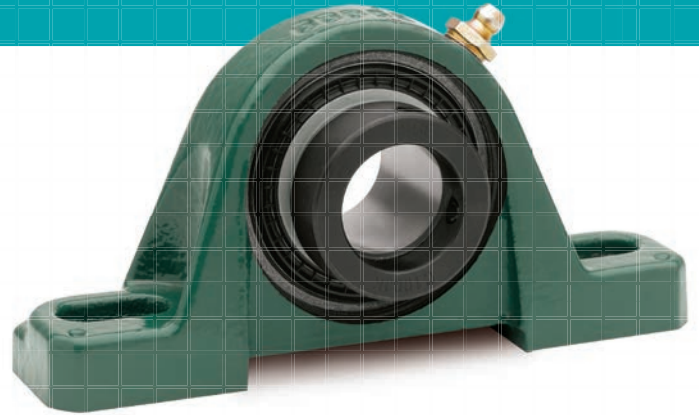

US BASED MANUFACTURING AND DISTRIBUTION

Consistent quality and product availability

- Local inventory available from over 250 distributor partners across the country
- Warehouses in Crossville, TN and Reno, NV
- Quick ship on most non-stock items within 3-5 days or less
- Bearing manufacturing capability, not just assembly of components


US BASED CUSTOMER SUPPORT

Responsiveness and ease of doing business

- Dedicated sales engineers in the US
- 24/7 customer service department in Greenville, South Carolina
- Application engineering support in Greenville, South Carolina



- 📍 Manufacturing Facility
- ★ Stocking Location
- Application & Customer Support

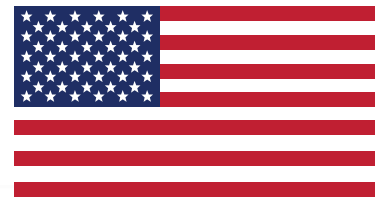


Born in the USA.
Supported in the USA.



STANDARD DUTY PACKAGE:

STANDARD SEALING PACKAGE:

Proven sealing system in many industrial environments

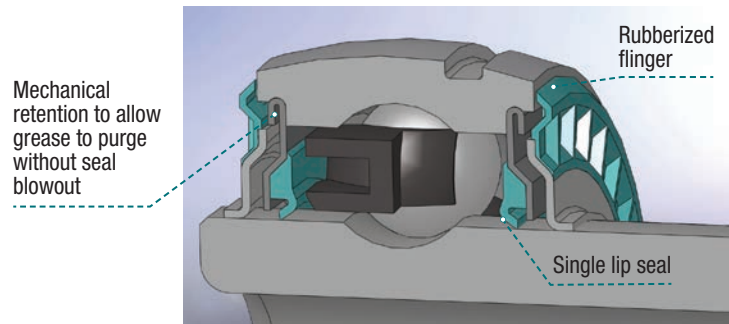

DualGuard seal:
Single lip seal with a rubberized flinger to prevent contamination.



Standard cage:
Fiberglass reinforced nylon construction allows for misalignment and does not absorb moisture.

Lubrication:
Unirex N2 lithium grease

Standard Warranty:
12 months in service / 18 months from date of manufacture



COMPLETE LINE OF ECCENTRIC COLLAR MOUNTED BALL BEARINGS DODGE ECCENTRIC COLLAR MOUNTED BALL BEARINGS

	PILLOW BLOCK	2-BOLT FLANGE	4-BOLT FLANGE	3-BOLT FLANGE	TAPPED BASE	PILOTED FLANGE	NARROW SLOT TAKE-UP
	P2B	F2B	F4B	F3B	TB	FC	NSTU
SXR/SXRB	1/2 - 2-15/16 *	1/2 - 2	1/2 - 2-15/16	N/A	3/4 - 2-3/16	1-1/16 - 2-7/16	3/4 - 2-7/16
SXV/SXVB	1/2 - 2-3/16 *	1/2 - 2-3/16	1/2 - 2-3/16	N/A	3/4 - 2-3/16	1-1/16 - 2-3/16	3/4 - 2-3/16
SLX	1/2 - 1-7/16	1/2 - 1-7/16	1-1/2 - 2-3/16	3/4 - 1-7/16	N/A	N/A	N/A

* Includes select SXRU/SXVU sizes


EXTREME DUTY PACKAGE (HARSH DUTY APPLICATIONS):

EXTREME DUTY SEALING PACKAGE:

Longer life and increased reliability



Mechanical retention to allow grease to purge without seal blowout

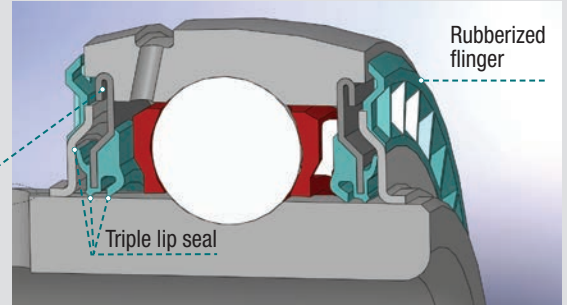

QuadGuard seal:

Triple lip seal with a rubberized flinger for added protection against contaminants in extremely harsh environments.



Max Life cage:

Patented 2 Piece cage design creates compartments to hold grease close to the ball track:

- Holds lubrication closer to the rolling element
- Resists contamination ingress
- Prevents lubrication washout

Lubrication:

Mobil PM220 synthetic grease leads to 4 times greater life compared to standard grease.

Extended warranty:

3 year warranty

WIDE SLOT TAKE-UP	TOP ANGLE TAKE-UP	CYLINDRICAL	HANGER
WSTU	GXR	CYLINDRICAL	HNG
3/4 - 2-15/16	1-15/16 - 2-15/16	7/8 - 1-7/16	1-1/16 - 2
3/4 - 2-3/16	N/A	N/A	N/A
N/A	N/A	N/A	N/A



SXR/SXRB and Extreme Duty versions are end cap ready.

INTERCHANGE CHART

PILLOW BLOCKS, TWO BOLT



SEALING	DODGE®	TIMKEN (FAFNIR)	PEER	AMI	BROWNING
Standard	P2B-SXRB-xxx	RAK x	HCP2xx-x	UGAK2xx-x	VPLE2xx
Economy	P2B-SXVB-xxx	VAK x	FHLP2xx-x	KHLP2xx-x	VPLE 1xx
Premium	P2B-SXRBED-xxx	TAK x	HCP2xx-x TRL	UGAK2xx-x RF	N/A

SEALING	DODGE	FYH	HUB CITY	IPTCI	LINK BELT
Standard	P2B-SXRB-xxx	NAPK2xx-x	PB220W x	NAPL2xx-x	P3Y2xxN
Economy	P2B-SXVB-xxx	N/A	PB220 x	SAPL2xx-xG	PL3W2xxU
Premium	P2B-SXRBED-xxx	NAPK2xx-x L3	PB220WM x	NAPL2xx-x L3	P3W2xxU E3

FLANGES, TWO BOLT



SEALING	DODGE	TIMKEN (FAFNIR)	PEER	AMI	BROWNING
Standard	F2B-SXR-xxx	RCJT x	HCFTS2xx-x	UGFJT2xx-x	VF2E2xx
Premium	F2B-SXRED-xxx	TCJT x	HCFTS2xx-x TRL	UGFJT2xx-x RF	N/A

SEALING	DODGE	FYH	HUB CITY	IPTCI	LINK BELT
Standard	F2B-SXR-xxx	NANFL2xx-x	FB230W x	NANFL2xx-x	FX3Y2xxN
Premium	F2B-SXRED-xxx	NANFL2xx-x L3	FB230HWM x	NANFL2xx-x L3	FX3Y2xxN E3

FLANGES, FOUR BOLT



SEALING	DODGE	TIMKEN (FAFNIR)	PEER	AMI	BROWNING
Standard	F4B-SXR-xxx	RCJ x	HCFS2xx-x	UGSLF2xx-x	VF4E2xx
Premium	F4B-SXRED-xxx	TCJ x	HCFS2xx-x TRL	UGSLF2xx-x RF	N/A

SEALING	DODGE	FYH	HUB CITY	IPTCI	LINK BELT
Standard	F4B-SXR-xxx	NANF2xx-x	FB220W x	NANF2xx-x w/L3	F3Y2xxN
Premium	F4B-SXRED-xxx	NANF2xx-x L3	FB220HWM x	NANF2xx-x L3	F3Y2xxN E3

BALDOR

A MEMBER OF THE ABB GROUP

Baldor Electric Company

P.O. Box 2400 • Fort Smith, AR 72902-2400 U.S.A.

Phone (479) 646-4711 • Fax (479) 648-5792

www.baldor.com