

# FRACTIONAL HORSEPOWER SERIES (F.H.P.): MFAL (FIXED BORE A & 4L V-BELT SERIES)

SHEAVES



## DID YOU KNOW THAT...

- Stock items include one set screw with standard keyseat
- Bulk packaged 10 per carton
- MFAM 144 bulk packaged 5 per carton

## IMPORTANT REMINDER



**CAUTION: DO NOT** use "A" gripnotch belts ratings with MFAL and MFAM sheaves.

## HOW TO ORDER

EXAMPLE: **MFAL104X3/4**

**M**

**FAL**

**104**

**X3/4**

**M:** MASKA LIGHT DUTY FAMILY

**FAL:** FRACTIONAL HORSEPOWER SERIE

**104:** OUTSIDE DIAMETER (10")\* (REFER TO THE DIMENSIONS TABLE FOR EXACT VALUE)

**X3/4:** BORE SIZE (3/4")


## DIMENSIONS

| Part No.        | List Price \$ | Diameter |             | Stock Bores |      |      |    | Dimensions |        |       |      | Wt (lbs) |
|-----------------|---------------|----------|-------------|-------------|------|------|----|------------|--------|-------|------|----------|
|                 |               | Outside  | D.D. A (4L) | 5/8"        | 3/4" | 7/8" | 1" | F          | L      | P     | C    |          |
| <b>MFAL54</b>   | <b>14.88</b>  | 4.93     | 4.78        | x           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 1.1      |
| <b>MFAL64</b>   | <b>15.56</b>  | 5.93     | 5.78        | x           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 1.5      |
| <b>MFAL74</b>   | <b>17.76</b>  | 6.93     | 6.78        | x           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 1.75     |
| <b>MFAL84</b>   | <b>20.24</b>  | 7.93     | 7.78        | x           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 2.2      |
| <b>MFAL94</b>   | <b>25.56</b>  | 8.93     | 8.78        | -           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 3.0      |
| <b>MFAL104</b>  | <b>28.20</b>  | 9.93     | 9.78        | -           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 2.7      |
| <b>MFAL114</b>  | <b>31.20</b>  | 10.93    | 10.78       | -           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 3.1      |
| <b>MFAL124</b>  | <b>37.40</b>  | 11.93    | 11.78       | -           | x    | (x)  | x  | 19/32      | 1 1/16 | 15/32 | -    | 3.5      |
| <b>MFAM144*</b> | <b>61.20</b>  | 14.16    | 14.00       | -           | -    | -    | x  | 11/16      | 1 3/32 | 13/32 | 1/32 | 5.2      |

Pitch Dia. for "A" (4L) belts = Datum Dia. +.26" = O.D. +.11"

( ) = Contact Maska for price and delivery

\*Note: This item is packaged 5 per carton.

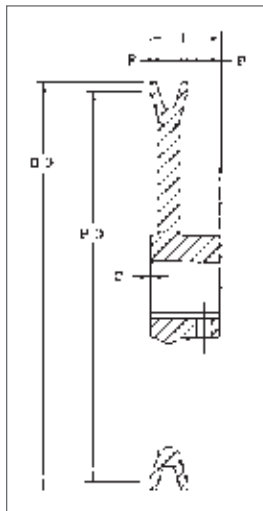

| Bore Range      | Keyseat       |
|-----------------|---------------|
| 1/2"            | None          |
| 5/8" - 7/8"     | 3/16" X 3/32" |
| 15/16" - 1 1/4" | 1/4" X 1/8"   |

