
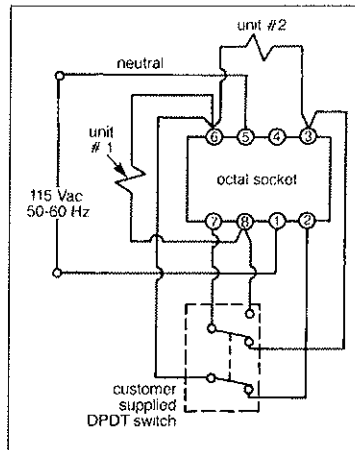
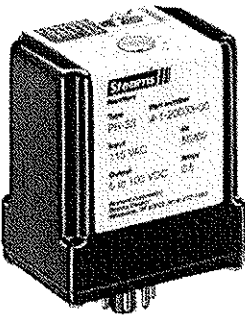
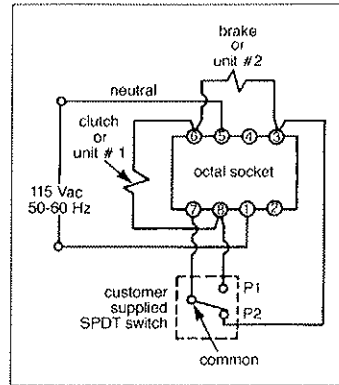


Rectifier Controls

Model PR-01

Two fixed 100 volt outputs.

- Modular plug-in design uses octal socket for easy mounting and wiring connection.
- Internally fused for overload protection.
- Operates one clutch or one brake, or both, one on at a time.

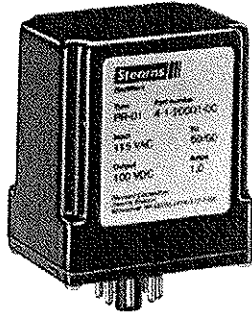

Model PR-33

One fixed 100 volt output and one adjustable 15-100 volt output to allow reduced torque starts or stops for "soft" cushioned engagement.

- Adjustable control on top of housing for easy accessibility.
- Modular plug-in design uses octal socket for each mounting and wiring connection.
- Internally fused for overload protection.
- Operates one clutch or one brake, or both, one on at a time.


Performance/List Price Data

Rectifier Part Number	AC Input Voltage	Nominal DC Output			Control Circuits		Switching Relay	List Price ②	Discount Symbol
		Volts	Max. Amp ①	Max. Watts	#1	#2			
PR-01 4-1-20001-00	115 50-60 Hz	100	1.0	100	Fixed	Fixed	No	\$266.00	X-1
PR-33 4-1-20033-00	115 50-60 Hz	15-100	0.5	50	Fixed	Variable	No	642.00	X-1

① Based on ambient temperature of 104°F.


② List prices subject to change without notice.

Enclosure dimensions apply to both PR-01 and PR-33.

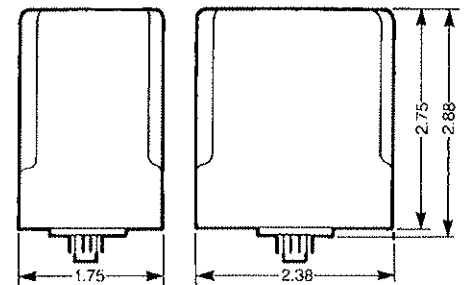


Octal Socket(s)


Supplied with terminal screws and clips

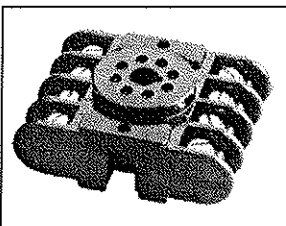

Part Number: 9-61-0153-00
Dimensions

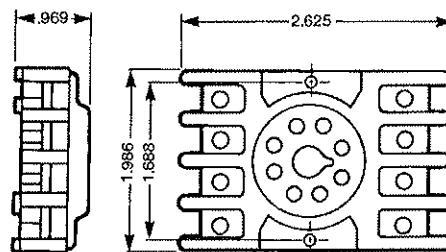

Part Number: 9-61-0153-01
Dimensions

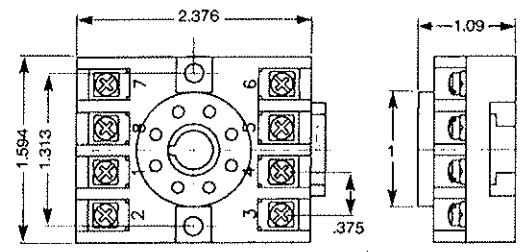

List Price Data

Octal Socket Part Number	List Price	Discount Symbol
9-61-0153-00	\$128.00	X-1
9-61-0153-01	48.00	X-1