

ABB BALDOR RELIANCE III

Customer information packet 762R

.5HP, 3600RPM, 1PH, 60HZ, 3420C, GRND

Specifications

Enclosure	GRND
Frame Material	Steel
Frequency	60.00 Hz 60.00 Hz
Motor Letter Type	Oil Capacitor Start and Run
Nameplate Output	.5
Number of Poles	2 2
Output @ Frequency	.500 HP @ 60 HZ
Phase	1 1
Product Style	GRINDER
Speed	3600 rpm 3600 rpm
Synchronous Speed @ Frequency	3600 RPM @ 60 HZ
Voltage	115 V
Voltage @ Frequency	115.0 V @ 60 HZ
Agency Approvals	CSA UL
Ambient Temperature	40 °C
Base Indicator	Rigid
Bearing Grease Type	Polyrex EM (-20F +300F)
Current @ Voltage	3.400 A @ 115.0 V
Duty Rating	CONT
Feedback Device	NO FEEDBACK
Heater Indicator	No Heater
Insulation Class	B
KVA Code	-
Motor Lead Quantity/Wire Size	4 @ 18 AWG
Motor Standards	Other
Motor Type	3420C
Mounting Arrangement	F1

Part Detail

Revision	BA
Type	AC
Mech. spec.	G7-373
Base	
Status	PRD/A
Elec. spec.	G7WG0030
Layout	G7LY0373
Eff. date	04-03-2025
CD Diagram	CD0279
Poles	02
Leads	4#18
Proprietary	False
Created date	01-01-0001

Overall Length	20.07 IN
Product Family	Grinder
Service Factor	1.00
Shaft Extension Location	Double Shaft
Shaft Rotation	Fixed Opposite Standard
Shaft Slinger Indicator	No Slinger
Speed Code	Single Speed
Starting Method	Direct on line
Thermal Device - Winding	None





Nameplate

NPO235			
CAT.NO.	762R		
HP	.5	VOLTS	115
PHASE	1	AMPS	3.4
HZ	60	RPM	3600
SER.NO			
SPEC.	G7-373-30		

Accessories

Part number	Description	Multiplier
GA16RE	PEDESTAL LIGHT INDUSTRIAL,STEEL-RED	A8
GA14R	PEDESTAL FABRICATED STEEL W/SHELVES-RED	A8
GA16R	PEDESTAL IND., CAST IRON 6" - 10" RED	A8
B73	7" 36 GRIT GRINDING WHEEL	A8
B74	7" 60 GRIT GRINDING WHEEL	A8
W70	W70 WIRE BRUSH WHEEL	A8
GA9R	PAIR LIGHTED EYESHIELDS-RED	A8
GA9SR	PAIR LIGHTED EYESHIELD W/ON-OFF-RED	A8
BQ1-015-CC	1PH Brake, NEMA 1,110-125 VAC, 50/60Hz	P1
BQ1-015-CP	1PH Brake, Panel 110-125 VAC, 50/60 Hz	

G7LY0373

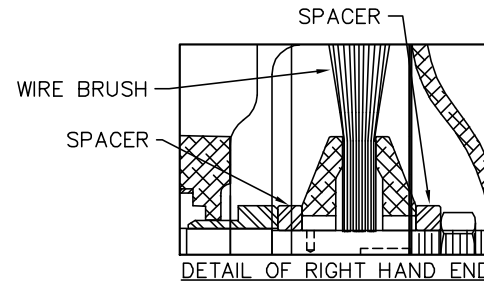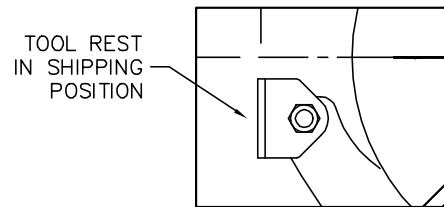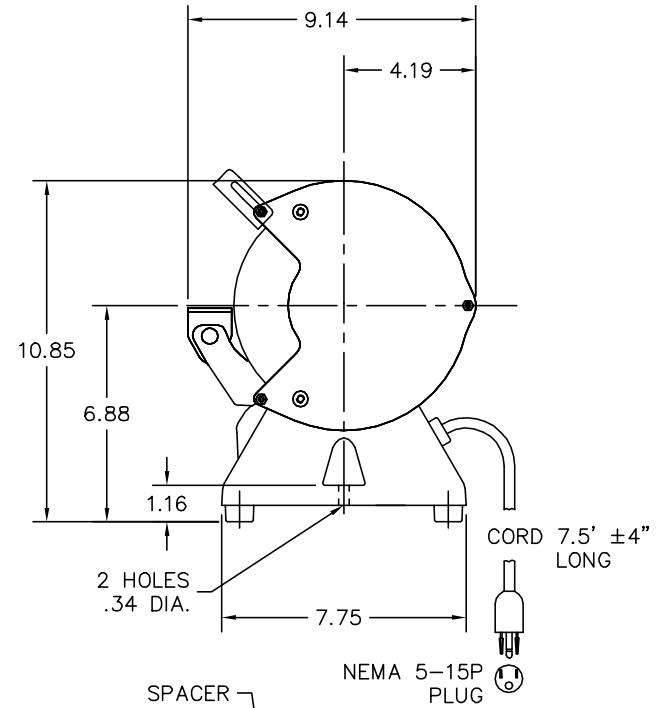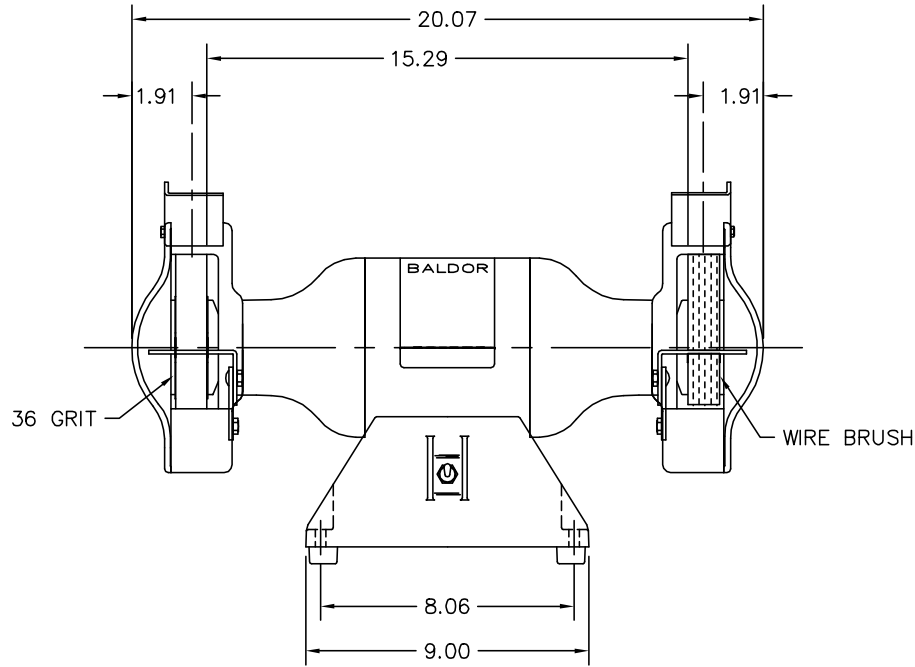

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT THE PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION.

REV. DESC: CHG'D CORD LENGTH TO 7.5' +/- 4" LONG		
REV. LTR: F	VERSION: 02	TDR: 000001219638
FILE: \AAA\00100\798	REVISED: 09:29:35 11/01/2023	BY: ENJFDO
MTL: -		

BALDOR - RELIANCE®

7" UTILITY GRINDER NON-EXHAUST MODEL 34C 115 VOLTS

SH 1 of 1

G7LY0373

