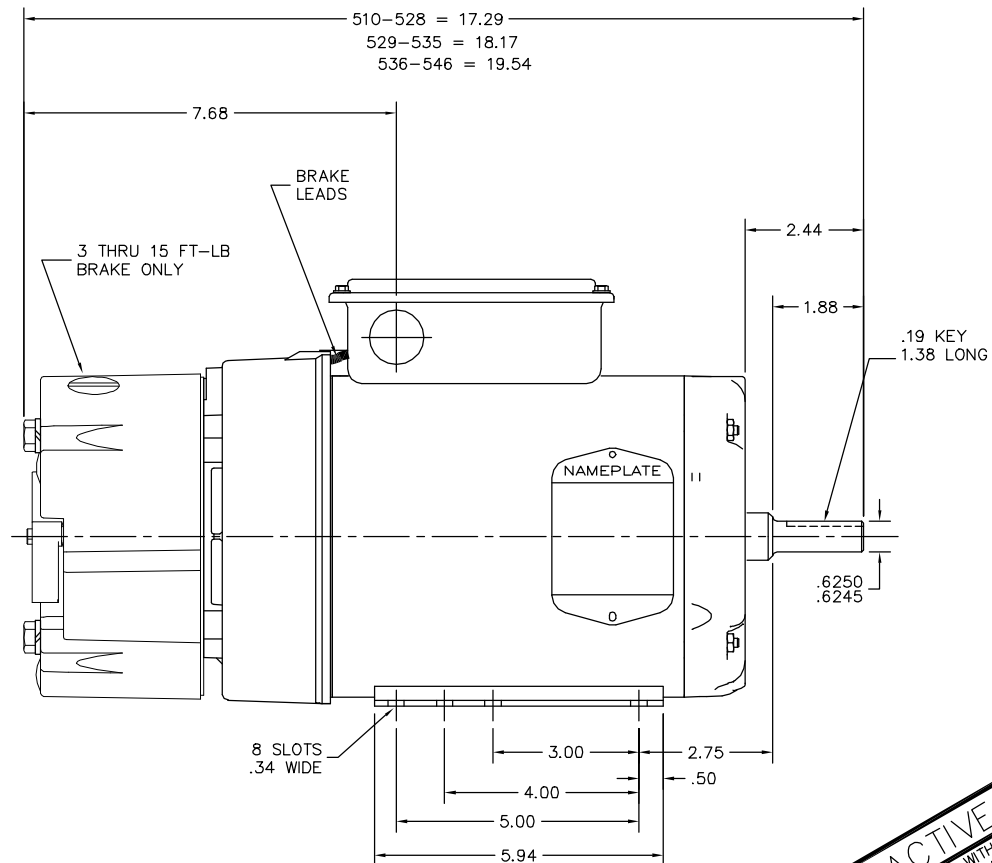


1 X ϕ .88 KNOCKOUT (PU. END)
2 X ϕ .88 KNOCKOUT (FR. END)

LEAD HOLE
 ϕ 1.12 W/PLUG

LEAD HOLE
1.12 DIA.

1.93

4.07

6.87

3.50 $\pm$.00
-.06

THERMAL
(WHEN REQ'D)

2.44

2.44

3.25

6.50

INACTIVE
DO NOT USE WITHOUT
UPDATING ALL REVISIONS

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT THE PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION.

REV. DESC: INA-NO ACTIVE SPECS - UPDATE IF REACTIVATED	VERSION: 04	TDR: 000001211789
REV. LTR: D	REVISED: 02:35:37 12/06/2023	BY: ENFRAJ0
FILE: \AAA\00153\678		
MTL: -		

BALDOR - RELIANCE®
HOR 56 TEFC M F3 W/DODGE 'D' SERIES BRK & 35CB4007, SPL BASE
SH 1 of 1