
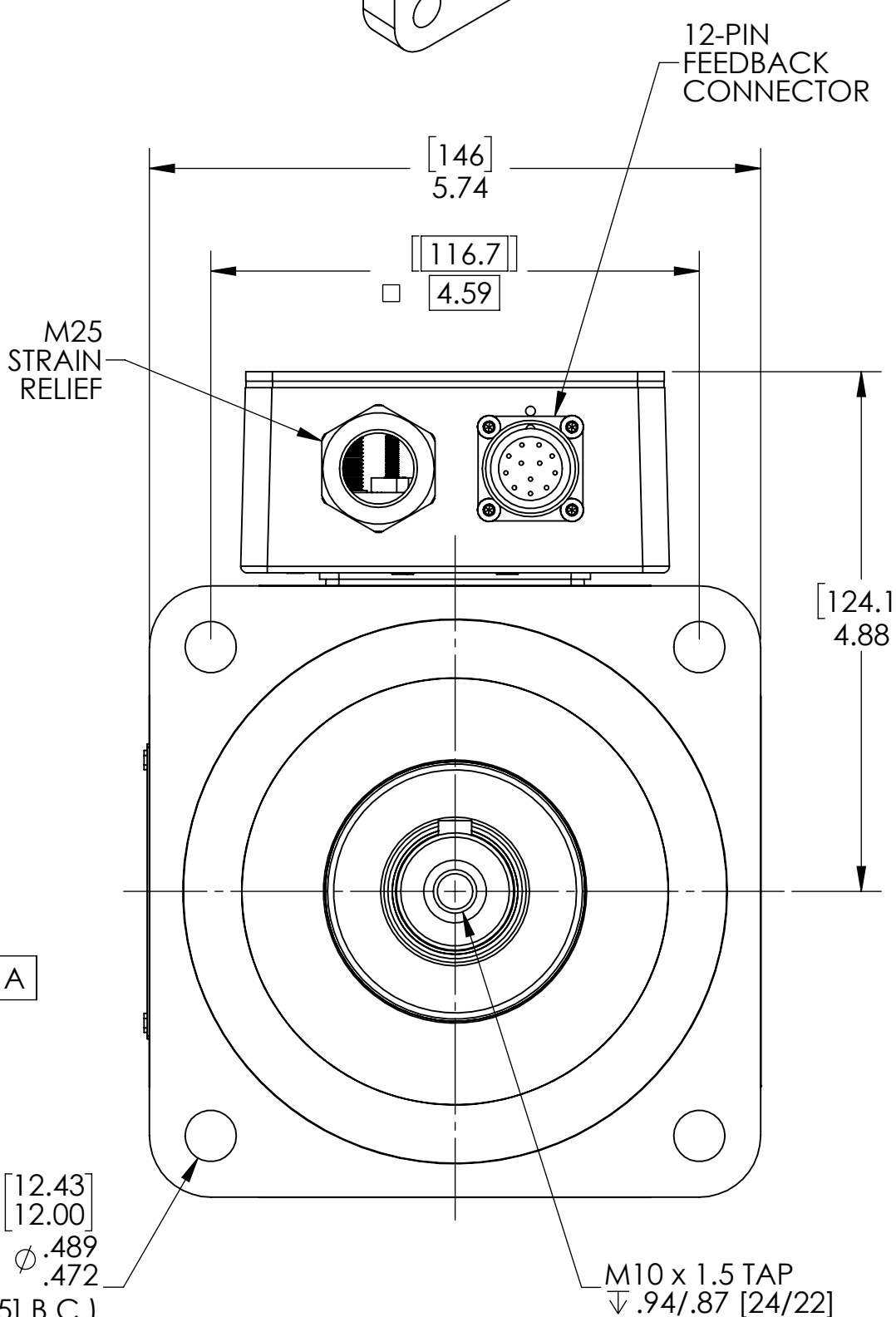
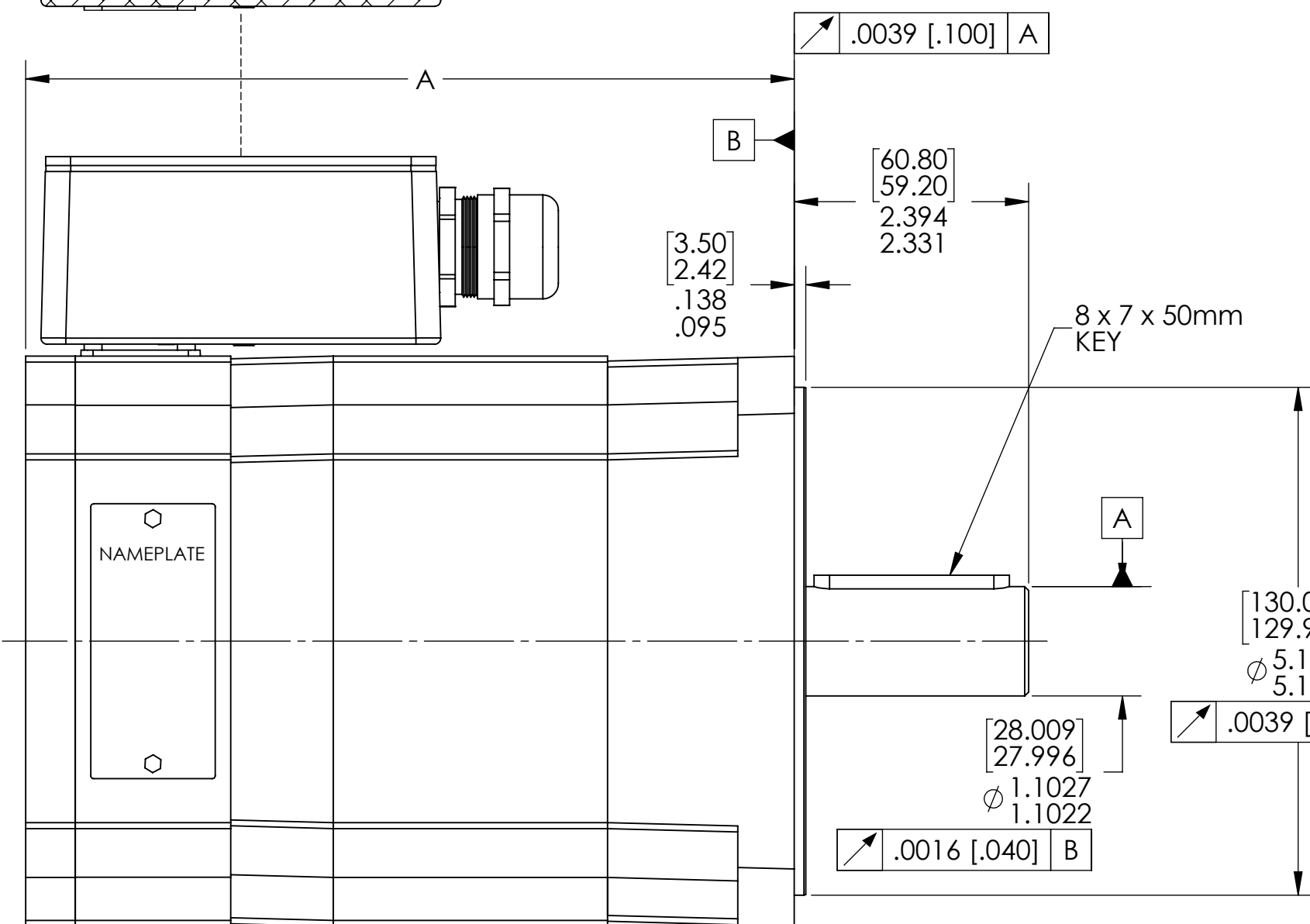
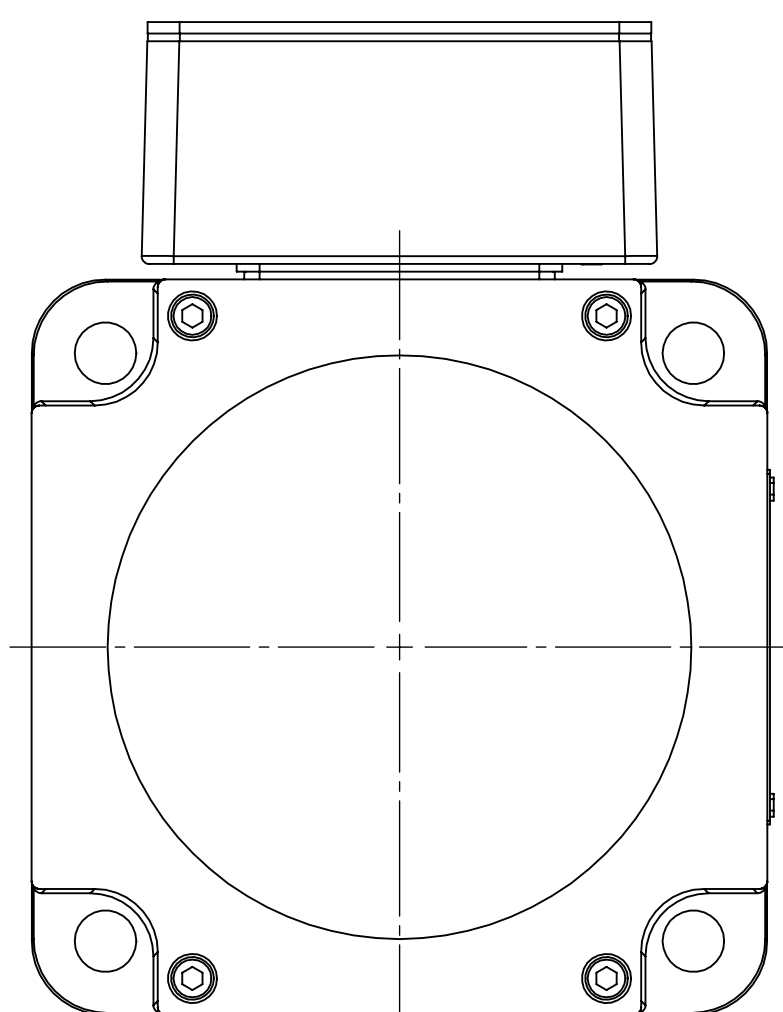
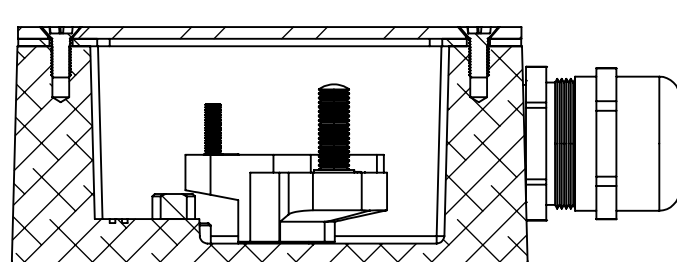
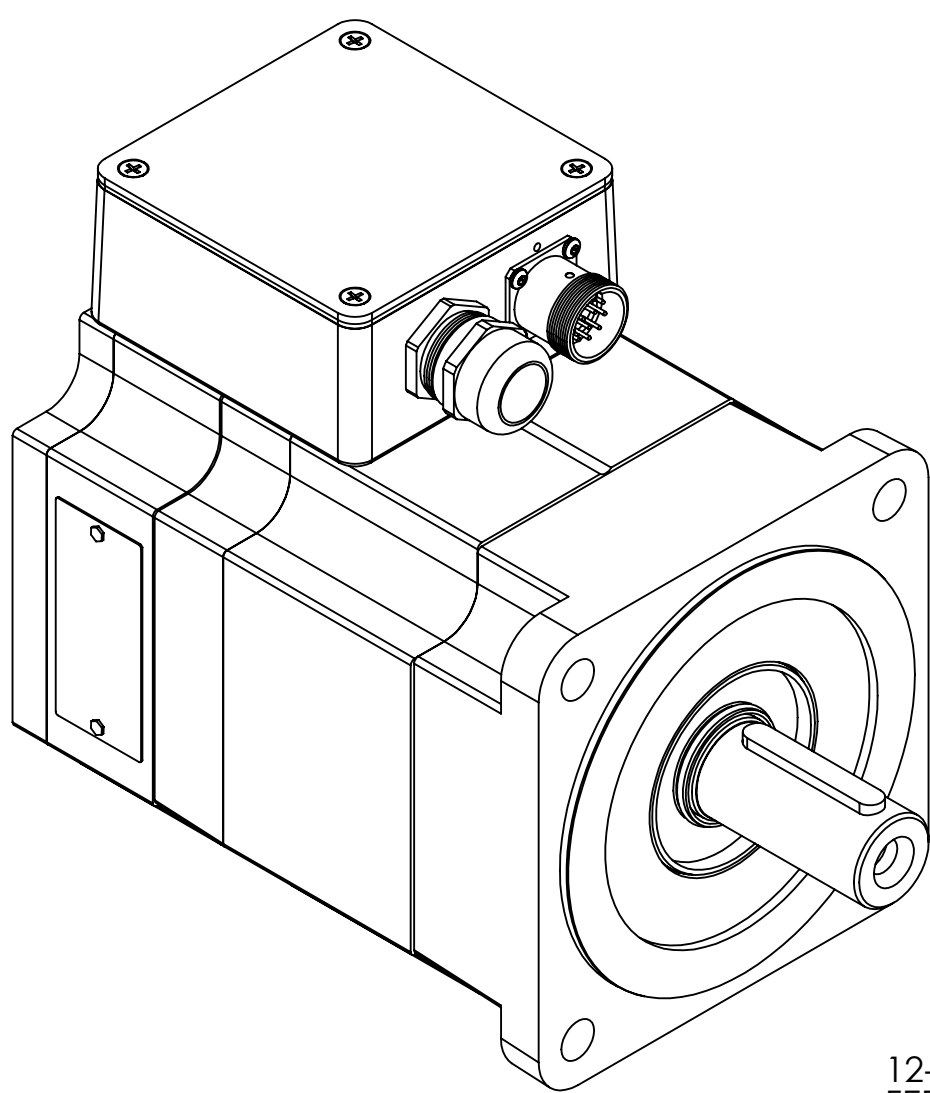
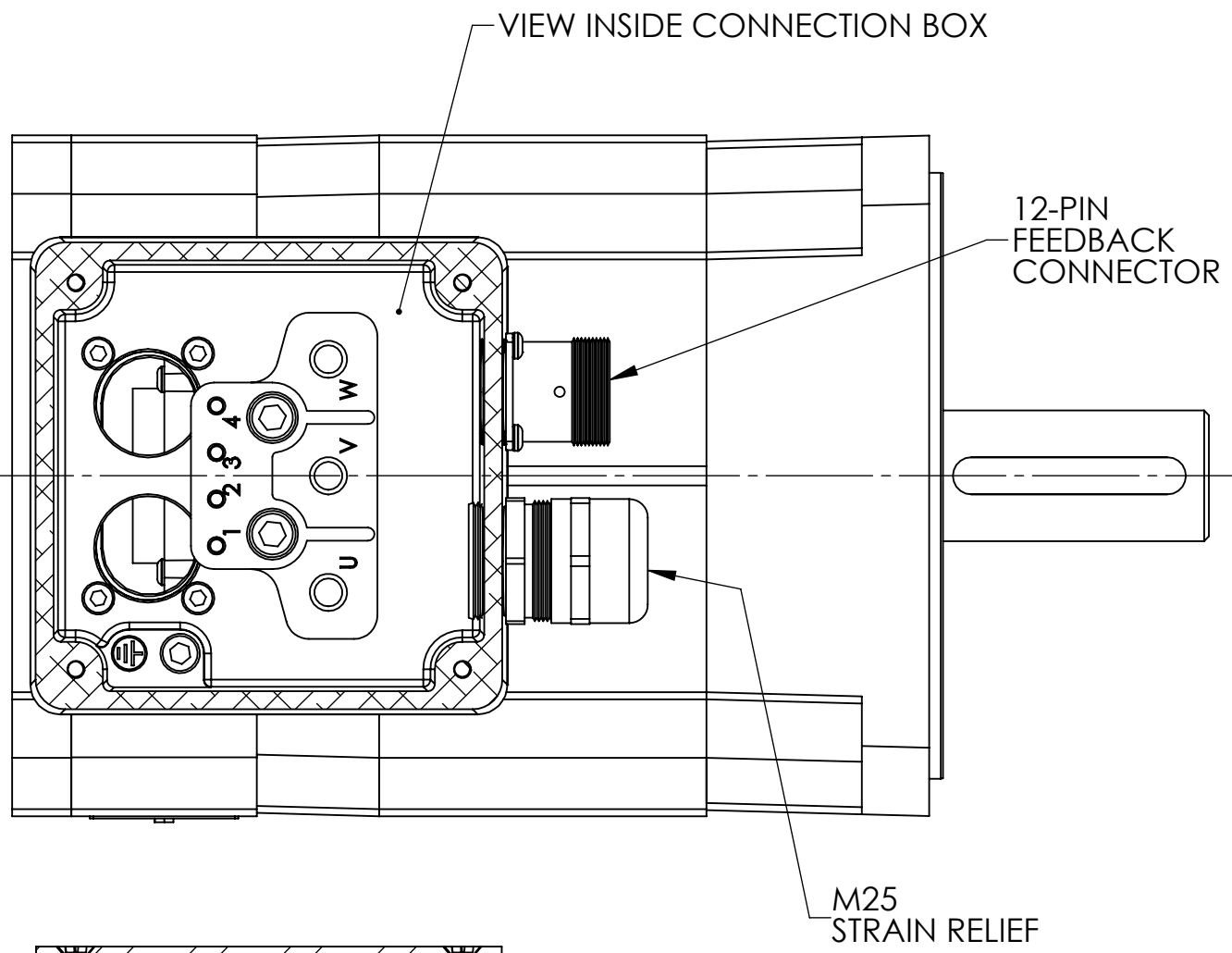


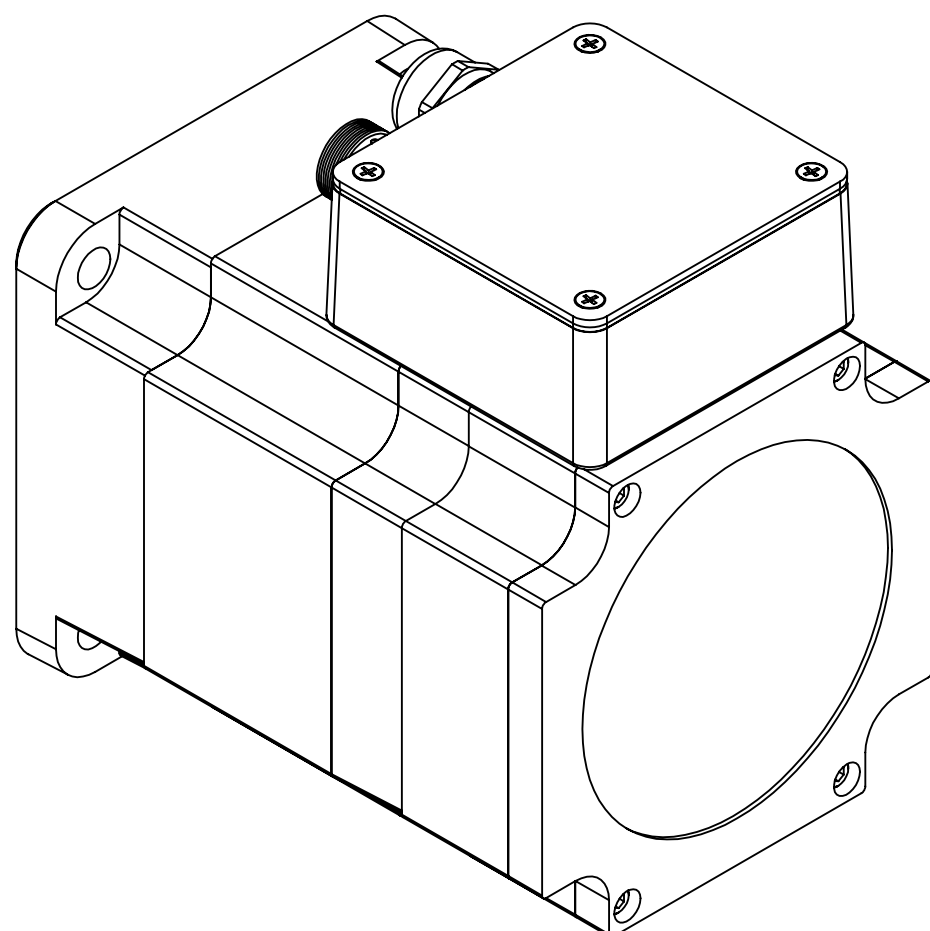

TOL UNLESS SPEC.
2 PLC INCH DEC. =
± .06" [1.5mm]
ANGLES ± 0.5°

REFERENCE	CODE	A
BSM100B-1	22	7.75 [196.8]
BSM100A/N-1	24	8.00 [203.1]
BSM100A/N-2	40	10.00 [253.9]
BSM100B-2	46	10.75 [273.0]
BSM100A/N-3	56	12.00 [304.7]
BSM100B-3	70	13.75 [349.2]
BSM100A/N-4	72	14.00 [355.5]
BSM100B-4	80	15.00 [380.9]

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT BALDOR'S PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION

REV. DESC: UPDATE LAYOUT GRAPHICS			
REV: F	VERSION: 03	REVISED: 04:11:43 01/30/2018	TDR: 000001059004
MODEL NO. S4LYP100			REF: -
BY: ENJEFD0			C

BALDOR

BSM100, 28D165, RESOLVER, K.O. BOX METRIC CONNECTOR