


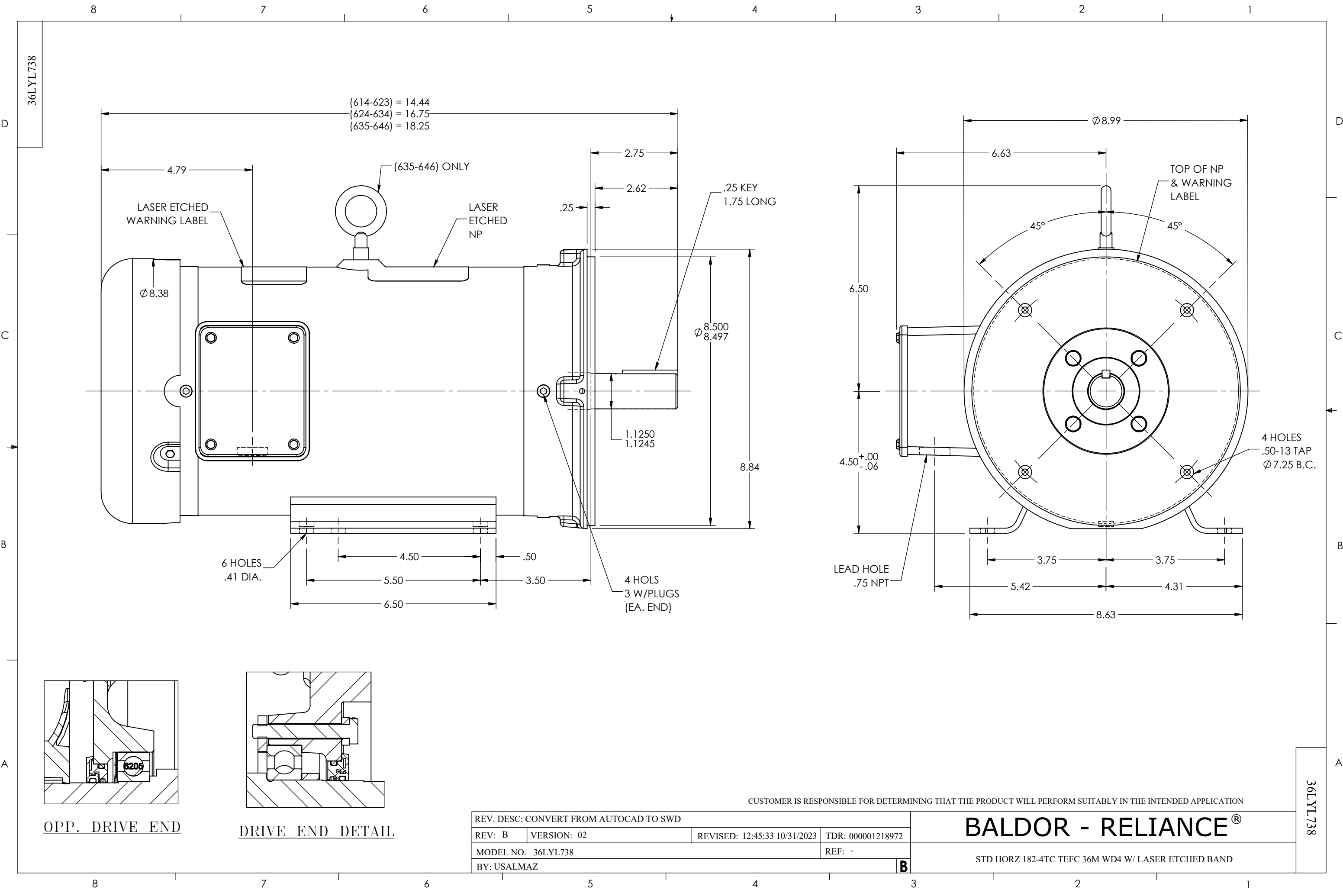

(614-623) = 14.44
(624-634) = 16.75
(635-646) = 18.25

LASER ETCHED
WARNING LABEL

LASER
ETCHED
NP

.25 KEY
1.75 LONG

Ø 8.500
8.497

1.1250
1.1245

8.84


6 HOLES
.41 DIA.

4 HOLS
3 W/PLUGS
(EA. END)


TOP OF NP
& WARNING
LABEL

4 HOLES
.50-13 TAP
Ø 7.25 B.C.

LEAD HOLE
.75 NPT

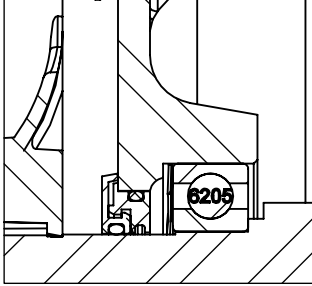

OPP. DRIVE END

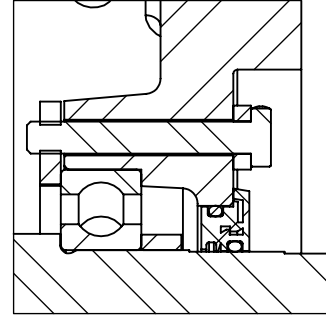

DRIVE END DETAIL

REV. DESC: CONVERT FROM AUTOCAD TO SWD			
REV: B	VERSION: 02	REVISED: 12:45:33 10/31/2023	TDR: 000001218972
MODEL NO. 36LYL738			REF: -
BY: USALMAZ			B

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT THE PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION

BALDOR - RELIANCE®

STD HORZ 182-4TC TEFC 36M WD4 W/ LASER ETCHED BAND

36LYL738