


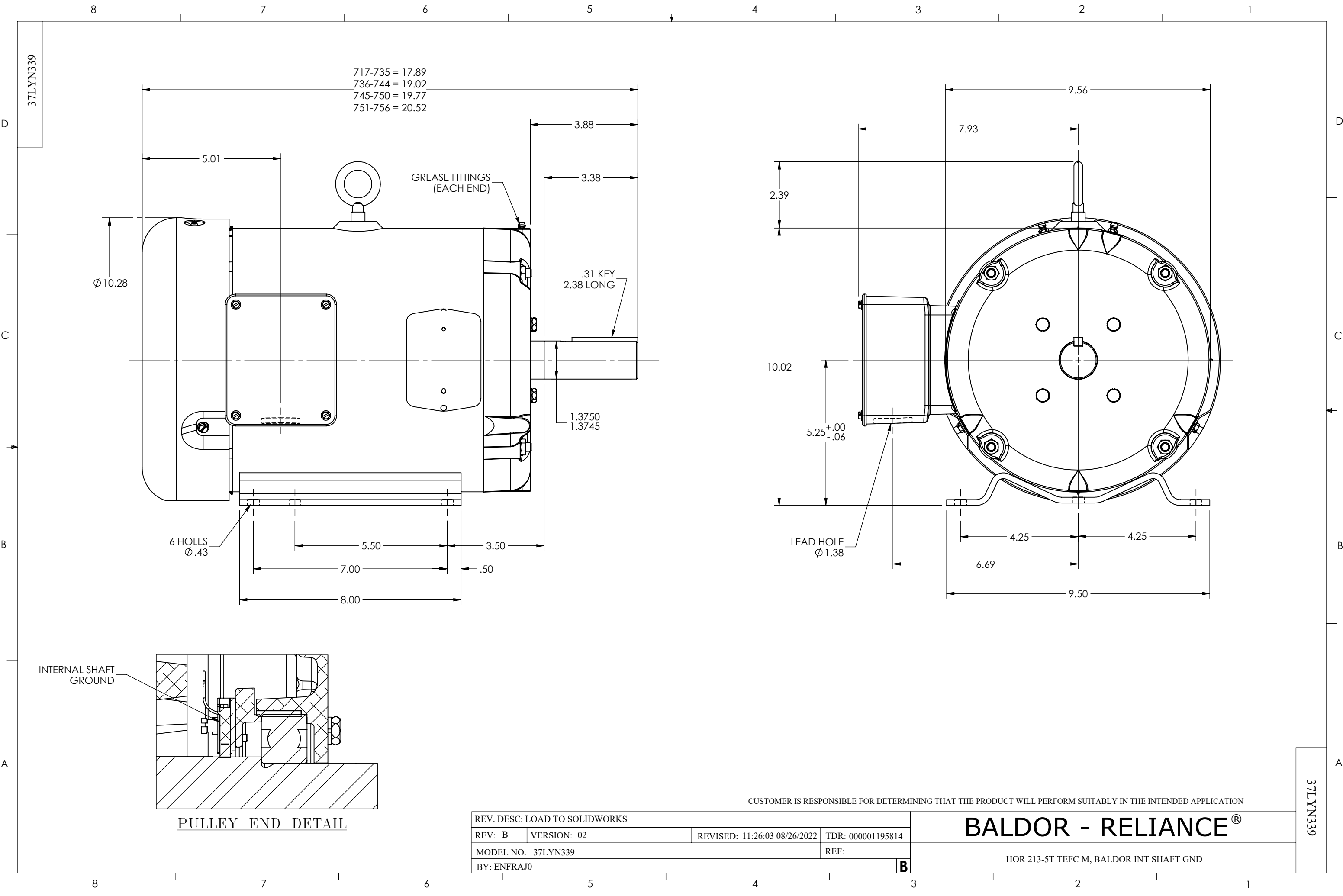

717-735 = 17.89
736-744 = 19.02
745-750 = 19.77
751-756 = 20.52

GREASE FITTINGS
(EACH END)

.31 KEY
2.38 LONG

1.3750
1.3745

6 HOLES
Ø .43

LEAD HOLE
Ø 1.38

INTERNAL SHAFT
GROUND

PULLEY END DETAIL

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT THE PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION

REV. DESC: LOAD TO SOLIDWORKS			
REV: B	VERSION: 02	REVISED: 11:26:03 08/26/2022	TDR: 000001195814
MODEL NO. 37LYN339			REF: -
BY: ENFRAJ0			B

BALDOR - RELIANCE®

HOR 213-5T TEFC M, BALDOR INT SHAFT GND

37LYN339