


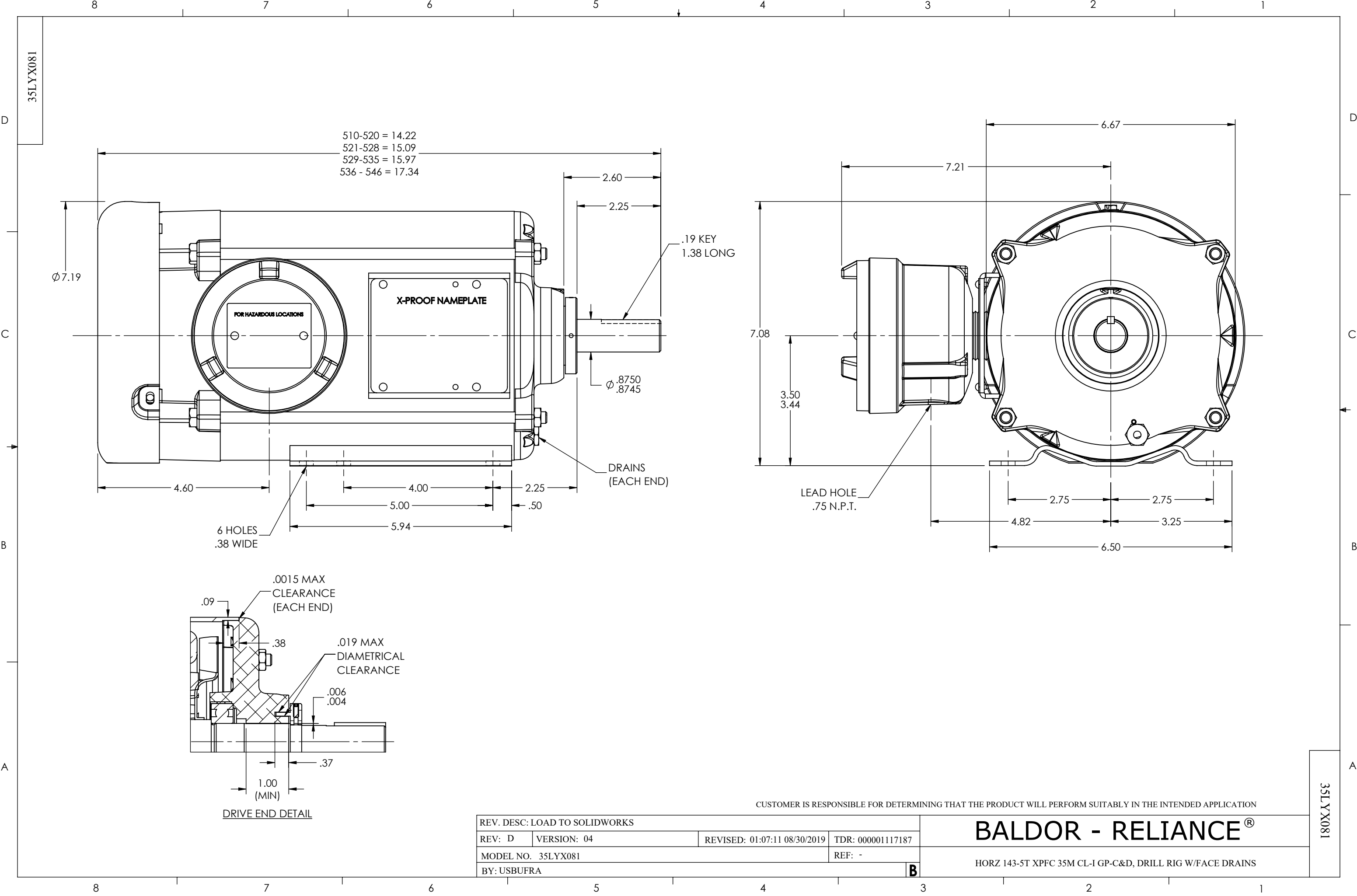

35LYX081

510-520 = 14.22
521-528 = 15.09
529-535 = 15.97
536 - 546 = 17.34

Ø7.19

X-PROOF NAMEPLATE

FOR HAZARDOUS LOCATIONS

.19 KEY
1.38 LONG

Ø .8750
Ø .8745

DRAINS
(EACH END)

6 HOLES
.38 WIDE

.0015 MAX
CLEARANCE
(EACH END)


.019 MAX
DIAMETRICAL
CLEARANCE

.006
.004

.37

1.00
(MIN)

DRIVE END DETAIL

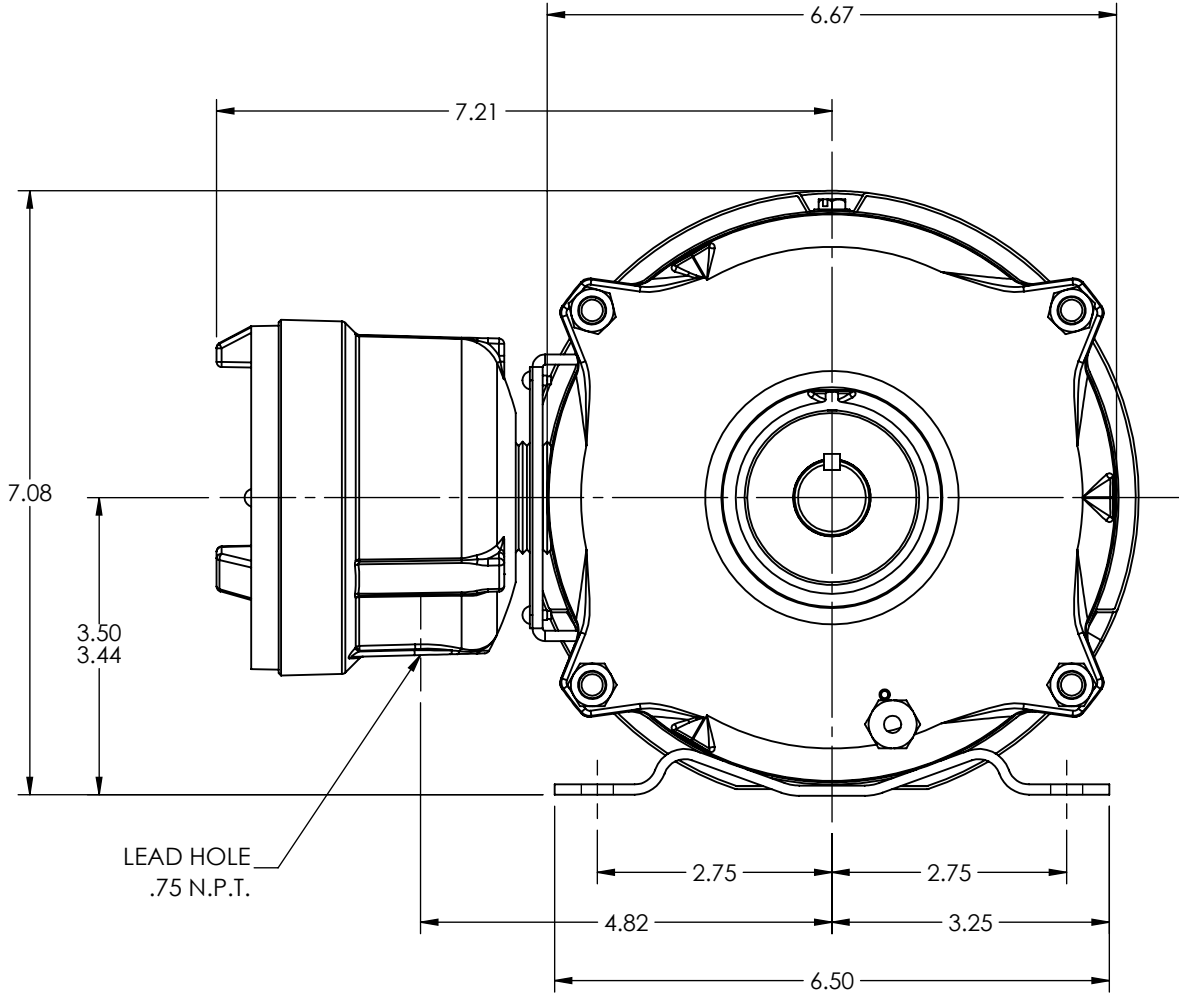

LEAD HOLE
.75 N.P.T.

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT THE PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION

REV. DESC: LOAD TO SOLIDWORKS			
REV: D	VERSION: 04	REVISED: 01:07:11 08/30/2019	TDR: 000001117187
MODEL NO. 35LYX081			REF: -
BY: USBUFRA			B

BALDOR - RELIANCE®

HORZ 143-5T XPFC 35M CL-I GP-C&D, DRILL RIG W/FACE DRAINS

35LYX081