

BALDOR • RELIANCE

Customer information packet

HDS130-1829BSKNN

HDS130-1829BSKNN, SMART-ABS ENCODER, KEY

Specifications

Bearing Grease Type	Polyrex EM
Dimensional Drawing Numbers	HD130LYA001
Nameplate Amps	14.5

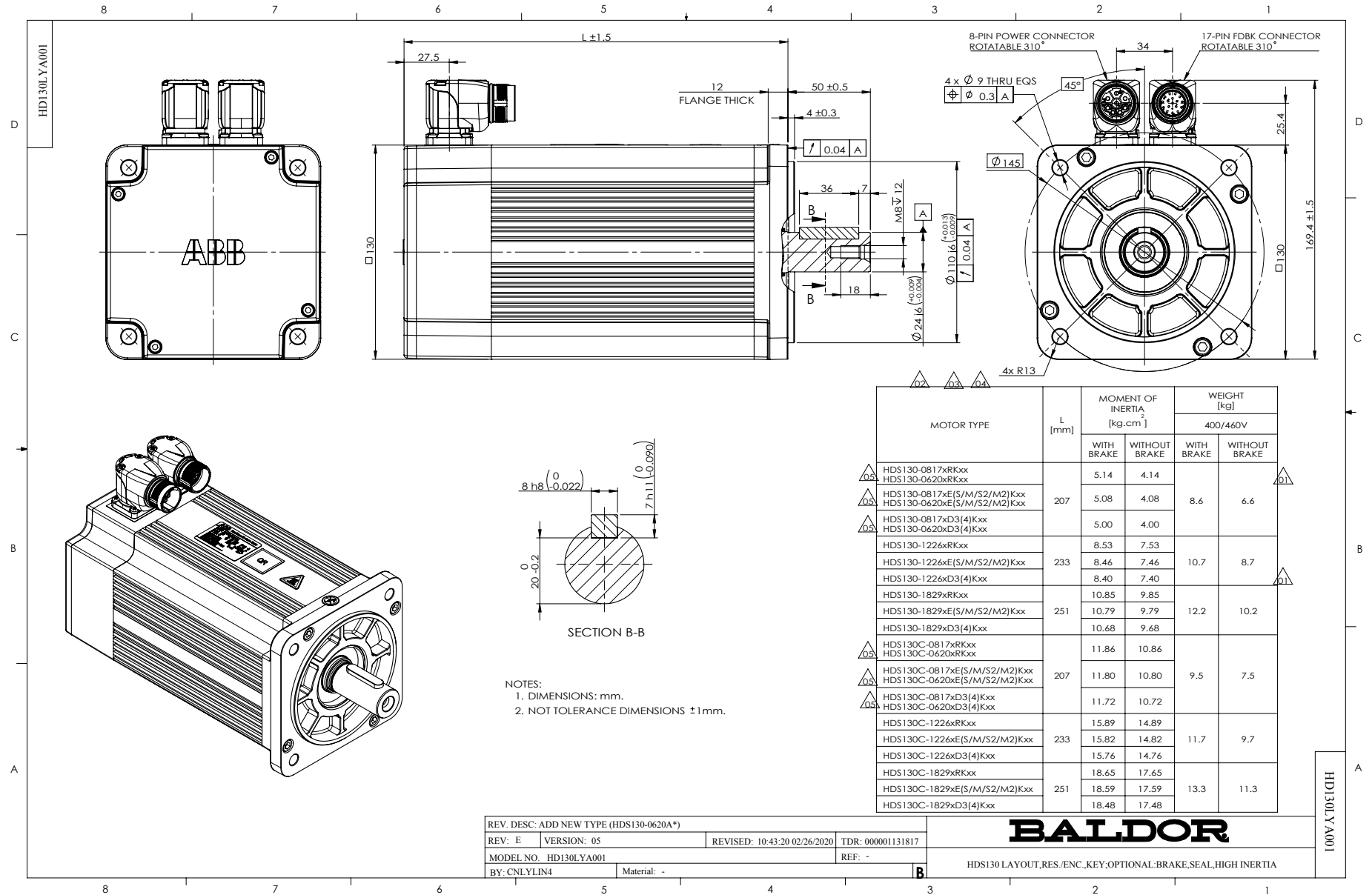
Part detail

Revision	F
Type	
Mech. spec.	
Base	
Status	PRD/A
Elec. spec.	
Layout	HD130LYA001
Eff. date	04-09-2018
CD Diagram	
Poles	
Leads	
Proprietary	False
Created date	08-15-2017

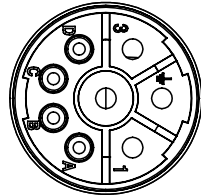
Nameplate

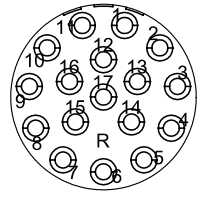
LB1577T01

MODEL:	HDS130-1829BSKNN								
PN	2.9	KW	TO	18.0	N.M	IO	14.5	A	
U	400	V	TP	54.0	N.M	IP	48.0	A	
NN/N MAX	1500/4000		RPM	3XPTC130					
FBK	S.ABS		IP	IP54	INS F				
BRK:	VDC/		N.M						
S/N									



CD2167A04

MOTOR & BRAKE LEADS			
 <p>WD1456A26 (INSERTION SIDE)</p>	PIN	FUNCTION	COLOR
	1	U (R)	BLACK
	2	GROUND (PE)	YELLOW/GREEN
	3	W (T)	BLUE
	4	V (S)	RED
	A	PTC	BLUE BLACK
	B	PTC	BLUE
	C	BRAKE	RED
	D	BRAKE	BLUE

SMART-ABS ENCODER LEADS			
 <p>WD1456A21 (INSECTION SIDE)</p>	PIN	FUNCTION	COLOR
	1	VCC	RED
	2	GND	BLACK
	3	VB	BROWN
	4	GND	BROWN/BLACK
	5	SD	BLUE
	6	$\overline{\text{SD}}$	BLUE/BLACK
	7	CASE GND	GRAY
	8-17		

REV. DESC: ENGINEERING CHANGE			
REV: E	VERSION: 05	REVISED: 04:28:49 03/04/2024	TDR: 000001227267
CD2167A04	MODEL NO. CD2167A04		REF: -
	BY: CNCONIE	Material: -	

BALDOR

CONNECTION DIAGRAM, POWER & SMART-ABS ENCODER

CD2167A04