


RPM AC TACHOMETER DIMENSIONS
NEMA FRAMES FL180 thru FL440 and IEC FRAMES FDL112 thru FDL280
DIMENSIONS ARE IN INCHES(mm)

DPFY, DPSV, TEPV, TESV, TENV & TEOA-PB
IC06, IC17, IC37, IC410, & IC416-PB

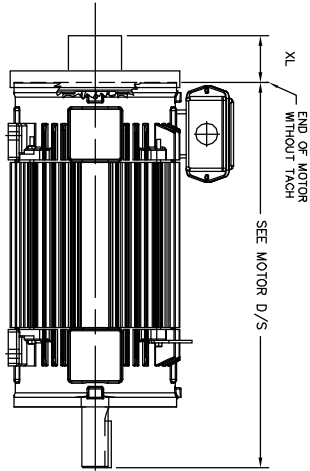


* THIS DIMENSION INCLUDES COVER FOR X/Y MOTOR.

TACH MODEL	XL Inches(mm)	LBS.
BEL DR DYNAPAR HS35	2.88 (74)	5
DYNAPAR H20	7.50(191)MAX.	10
NORTHSTAR HS35M	3.31 (84)	10
NORTHSTAR ST67	2.88 (74)	5
DYNAPAR HS6	10.56 (268)	40
AVTRON M3 DR M4	3.62 (92)	10
TAMAGAWA TS5013(X7)	6.00 (152)	10
NORTHSTAR ST56	2.88 (74)	5
NORTHSTAR ST85	2.00 (51)	5
BEL H38D	10.19 (259)	15
TAMAGAWA TS2151	2.64 (67)	15
BEL H25	7.50 (191)	15
DYNAPAR HS20	2.00 (50.8)	5
DYNAPAR X25	12.88 (327)	10
STEGMANN SRM25	7.25 (184.4)	10
NORTHSTAR HS035	3.00 (76.2)	10
HEIDENHAIN EQM425	2.5 (63.5)	5
AVTRON HS35M	4.19 (106.4)	5
HEIDENHAIN ERN480	5.00 (76.2)	5
DYNAPAR HD25	7.00 (177.8)	10
DYNAPAR H22	3.62 (92.1)	5
AVTRON M285	2.54 (64.5)	9
AVTRON AV850	2.54 (64.5)	9
AVTRON AV56	4.50 (115)	15
HS038	3.30 (84)	5
HS025	3.30 (84)	2
NORTHSTAR RT8	3.25 (83)	15
DYNAPAR HA625	5.88 (150)	10
AVTRON AV485	9.50 (241)	18
AVTRON AV32	1.93 (49)	.7
DYNAPAR RH25	3.80 (97)	1.6
AVTRON AV85	2.40 (64.5)	3


TEAO-BC, IC416-BC
EXCLUDES NEMA FRAMES FL320 THRU FL440
AND
IEC FRAMES FDL200 THRU FDL280

TACH MODEL	XL Inches(mm)	LBS.
BEL DR DYNAPAR HS35	4.50 (115)	10
DYNAPAR H20	4.50 (115)	15
AVTRON M3 DR M4	4.50 (115)	10
NORTHSTAR HS35M	4.50 (115)	15
NORTHSTAR ST56	4.50 (115)	10
NORTHSTAR ST67	4.50 (115)	10
NORTHSTAR ST85	4.50 (115)	5
TAMAGAWA TS5008, TS5013	4.50 (115)	10
AVTRON HS20	4.50 (115)	15
STEGMANN SRM25	4.50 (115)	10
STEGMANN SRS/SRM50	4.50 (115)	3
STEGMANN SRS60	4.50 (115)	15
H20 & H25E	4.50 (115)	15
AVTRON HS35M	4.50 (115)	10
AVTRON AV85	4.50 (115)	10
AVTRON M56	4.50 (115)	5
AVTRON AV67	4.50 (115)	10
HS038	4.50 (115)	5
TS2014	4.50 (115)	10
AVTRON HS45	4.50 (115)	15
DYNAPAR HS038M	4.50 (115)	15
AVTRON AV32	4.50 (115)	.7
AVTRON AV850	4.50 (115)	9

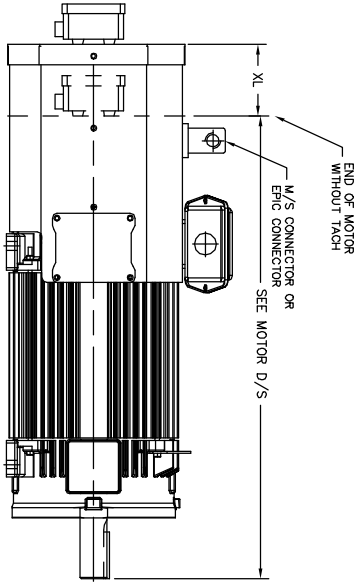

TEFC, IC411

TACH MODEL	XL Inches(mm)	LBS.
BEL HS35	2.88 (74)	7
NORTHSTAR HS35M	3.31 (84)	10
DYNAPAR H20	3.75 (95)	15
DYNAPAR HS35, HSD38	2.88 (74)	7
H20(X7)	9.75 (248)	35
EQM425	7.90 (201)	35
AVTRON HS35M	4.19 (106)	2
STEGMANN SRM50	3.75 (95)	1
DYNAPAR HS20	2.00 (51)	1
NORTHSTAR HS035	2.81 (71)	2
NORTHSTAR HS038	3.30 (84)	5
AVTRON AV32	1.93 (49)	.7

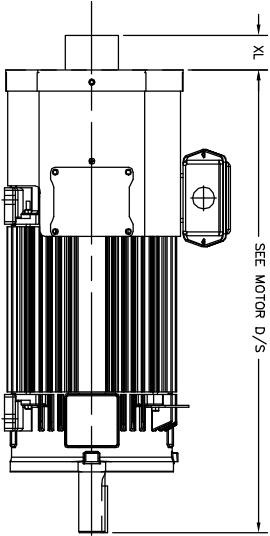

CUSTOMER IS RESPONSIBLE FOR DETERMINING THAT BALDOR'S PRODUCT WILL PERFORM SUITABLY IN THE INTENDED APPLICATION.

REV. DESC: ADD AV85	VERSION: 25	TDR: 000001111552
REV. LTR: AA	REVISED: 03:54:15 06/26/2019	BY: RGGRWM
FILE: \RGG\00003\694		
MTL: -		

BALDOR - RELIANCE®

DIM SHT TACH DIM NEMA FL180 - FL440 IEC FDL112 - FDL280

SH 1 of 1