


# BALDOR•DODGE® ISAF END COVERS SAFE AND RELIABLE

Dodge ISAF End Covers ensure safe and reliable operation by preventing access to rotating shafts and eliminating contaminants from coming in contact with the seal.

Dodge ISAF End Covers are designed for durability and ease of installation. Both open and closed versions are available to fit your application needs.

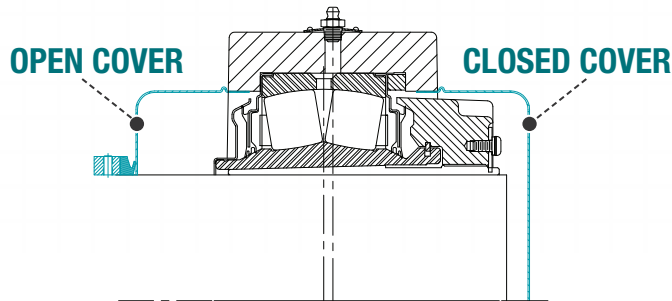

## DESIGNED FOR SAFETY & RELIABILITY

Dodge ISAF End Covers are made from durable steel with a special coating for corrosion protection and drain hole for any moisture. End covers also provide an additional layer of reliability by providing a barrier for contaminants.

## EASY INSTALLATION


ISAF housings are designed with a generous lead in chamfer and close tolerance bore for accurate end cover fit and ease of installation.

# BALDOR•DODGE® ISAF END COVERS

## PART NUMBER CHART

ISAF End Covers are available in both open and closed versions to fit your application needs.

SHAFT SIZE	CLOSED END COVER		OPEN END COVER	
	PART NUMBER	PART DESCRIPTION	PART NUMBER	PART DESCRIPTION
30mm	069960	IPEC08 (107)	070251	IPECO-08-30mm
1-7/16	069960	IPEC08 (107)	070164	IPECO-08-107
35mm	069960	IPEC08 (107)	070252	IPECO-08-35mm
1-11/16	069961	IPEC09 (111)	070168	IPECO-09-111
40mm	069961	IPEC09 (111)	070253	IPECO-09-40mm
1-15/16	069962	IPEC10 (115)	070172	IPECO-10-115
2	069962	IPEC10 (115)	070173	IPECO-10-200
50mm	069962	IPEC10 (115)	070255	IPECO-10-50mm
2-3/16	069963	IPEC11 (203)	070174	IPECO-11-203
55mm	069963	IPEC11 (203)	070256	IPECO-11-55mm
2-7/16	069964	S2IPEC13 NEW DESIGN (206-208)	070178	S2IPECO-13-207
60mm	069964	S2IPEC13 NEW DESIGN (206-208)	070257	IPECO-13-60mm
2-11/16	069965	IPEC15 (215)	070180	IPECO-15-211
2-15/16	069965	IPEC15 (215)	070182	IPECO-15-215
3	069965	IPEC15 (215)	070183	IPECO-15-300
65mm	069965	IPEC15 (215)	070258	IPECO-15-65mm
70mm	069965	IPEC15 (215)	070259	IPECO-15-70mm
75mm	069965	IPEC15 (215)	070260	IPECO-15-75mm
3-7/16	069966	IPEC18 (307)	070186	S2IPECO-18-307
80mm	069966	IPEC18 (307)	070261	IPECO-18-80mm
85mm	069966	IPEC18 (307)	070262	IPECO-18-85mm
3-15/16	069967	S2IPEC20 NEW DESIGN (311-400)	070189	S2IPECO-20-315
90mm	069967	S2IPEC20 NEW DESIGN (311-400)	070263	IPECO-20-90mm
100mm	069967	S2IPEC20 NEW DESIGN (311-400)	070264	IPECO-20-100mm
4-7/16	069968	S2IPEC22 NEW DESIGN (407-408)	070191	S2IPECO-22-407
4-1/2	069968	S2IPEC22 NEW DESIGN (407-408)	070192	S2IPECO-22-408
110mm	069968	S2IPEC22 NEW DESIGN (407-408)	070265	IPECO-22-110mm
4-15/16	069969	S2IPEC26 NEW DESIGN (415-500)	070193	S2IPECO-26-415
5	069969	S2IPEC26 NEW DESIGN (415-500)	070194	S2IPECO-26-500
115mm	069969	S2IPEC26 NEW DESIGN (415-500)	070266	IPECO-26-115mm
125mm	069969	S2IPEC26 NEW DESIGN (415-500)	070267	IPECO-26-125mm
5-7/16	069983	IPEC-28	069933	IPECO-28-507
5-1/2	069983	IPEC-28	069934	IPECO-28-508
140mm	069983	IPEC-28	070268	IPECO-28-140mm
5-15/16	069984	IPEC-32	069935	IPECO-32-515
6	069984	IPEC-32	069936	IPECO-32-600
150mm	069984	IPEC-32	070269	IPECO-32-150mm
6-7/16	069985	IPEC-36	069937	IPECO-36-607
6-1/2	069985	IPEC-36	069938	IPECO-36-608
160mm	069985	IPEC-36	070270	IPECO-36-160mm
6-15/16	069985	IPEC-36	069939	IPECO-36-615
7	069985	IPEC-36	069940	IPECO-36-700
170mm	069985	IPEC-36	070271	IPECO-36-170mm

 New range for large shaft sizes.

# BALDOR

A MEMBER OF THE ABB GROUP

**Baldor Electric Company**

P.O. Box 2400 • Fort Smith, AR 72902-2400 U.S.A.

Phone (479) 646-4711 • Fax (479) 648-5792

[www.baldor.com](http://www.baldor.com)